



AIR CHUCK FOR RUNNER / MOUNTING PLATE FOR AIR CHUCKING RUNNER  
**RUNNER CHUCK / MOUNTING PLATE (FOR RUNNER CHUCK)**

PARALLEL AIR CHUCK  
**PARALLEL CHUCK**  
 — SINGLE ACTING TYPE / LONG STROKE TYPE —




**RC-HC20BPX**  
(without sensor)

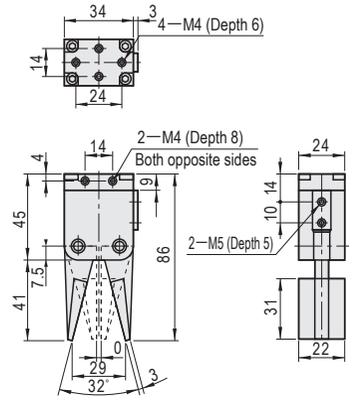

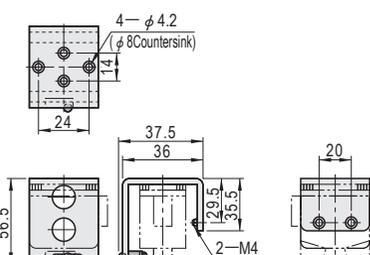

**RC-HC20BPX-S**  
(with sensor)

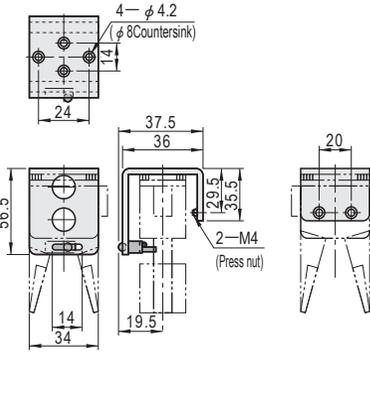

**Basic Specifications**

- Actuation type: Single acting type
- Operating fluid: Compressed air
- Operating pressure: 0.2-0.6 MPa
- Operating temperature range: -10-60°C (not frozen)

Weight (g) <sup>1</sup>	Part Number			Unit price 1~10 pcs
	Type	No.	Sensor	
150	RC-HC	20BPX	(No)	<b>Quotation</b>
225			(Yes)	

**Order** **Part Number**  
 RC-HC20BPX  
 RC-HC20BPX-S


**Days to Ship** **Quotation**

<sup>1</sup>The weight is an approximate value. Consider it a guideline. Please check with our WOS for the purchase order that exceeds the displayed quantity.



**RC-BPLH** (RC-HC20BPX without sensor)  
**RC-BPLHS** (RC-HC20BPX-S with sensor)

**Mounting Hole×1 (D5.5×1) ■ Mounting Hole×2 (D5.5×2)**

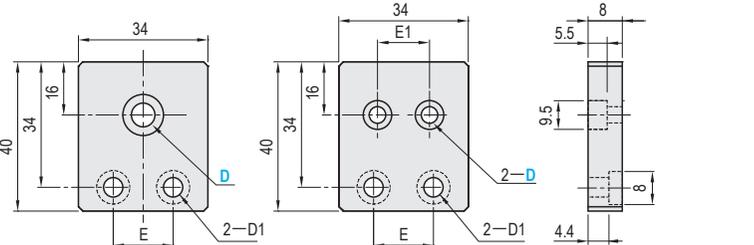

**Mounting plate for runner chuck**

Bolt for fixing runner chuck	Part Number	Mounting hole size D	Unit price 1~10 pcs
M4×P0.7 2 pcs (Accessories)	<b>RC-BPLH20</b> (without sensor)	<b>1D5.5</b> (Mounting hole×1)	<b>Quotation</b>
	<b>RC-BPLHS20</b> (without sensor)	<b>2D5.5</b> (Mounting hole×2)	

**Mounting Clamp (Mounting Bolt Set)**

Part Number	Mounting hole size D	Mounting bolt	Unit price 1~10 pcs
<b>RC-BPLH20</b> (without sensor)	<b>1D5.5</b> (Mounting hole×1)	<b>AS1M5</b> (M5: 1 pc)	<b>Quotation</b>
		<b>AF1M5</b> (M5: 1 pc)	
<b>RC-BPLHS20</b> (without sensor)	<b>2D5.5</b> (Mounting hole×2)	<b>AS2M5</b> (M5: 2 pcs)	
		<b>AF2M5</b> (M5: 2 pcs)	

Please check with our WOS for the purchase order that exceeds the displayed quantity.

Please check with our WOS for the purchase order that exceeds the displayed quantity.

**Specifications and Dimensional Details**

Part Number	Mounting hole	E	E1	D	D1	Weight (g) <sup>1</sup>	Applicable cylinder
RC-BPLH20-1D5.5	Mounting hole×1	—	—	—	—	23	RC-HC20BPX (without sensor)
RC-BPLH20-2D5.5	Mounting hole×2	14	12	5.5	4.5		RC-HC20BPX-S (with sensor)
RC-BPLHS20-1D5.5	Mounting hole×1	—	—	—	—	23	RC-HC20BPX-S (with sensor)
RC-BPLHS20-2D5.5	Mounting hole×2	20	12	5.5	4.5		RC-HC20BPX-S (with sensor)

**Bolt Set Details**

Mounting bolt	Mounting bolt details	Applicable parts
AS1M5 (M5, 1 pc)	M5×P0.8-12 (CB5-12) : 1 pc	Shaft: AT-HAS□ Pipe joint: FP-FMJT
AS2M5 (M5, 2 pcs)	M5×P0.8-12 (CB5-12) : 2 pcs	
AF1M5 (M5, 1 pc)	M5×P0.8-8 (CB5-8) : 1 pc	Aluminum frame
AF2M5 (M5, 2 pcs)	M5×P0.8-8 (CB5-8) : 2 pcs	HFS5-2020 / HF5FN5-1020


**Part Number** — **D** — **Mounting bolt**

**RC-BPLH20** — **1D5.5**  
**RC-BPLHS20** — **2D5.5** — **AF2M5**

**Days to Ship** **Quotation**



**HC-CHHDLS**

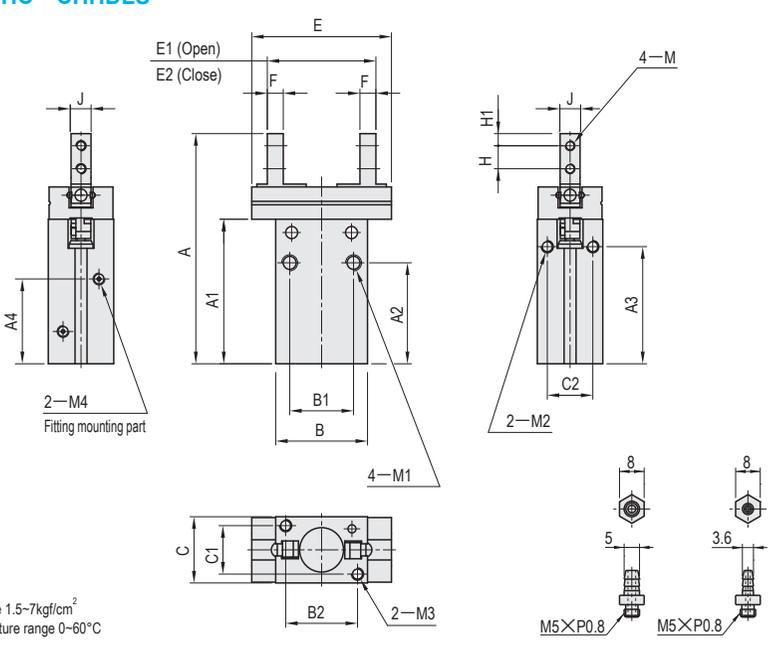

**Basic Specifications**

- Actuation type: Single acting type
- Operating pressure: 1.5-7kgf/cm<sup>2</sup>
- Operating fluid: Air
- Operating temperature range: 0-60°C

A	A1	A2	A3	A4	B	B1	B2	C	C1	C2	E	E1	E2	F	H	H1	J	M	M1	M2	M3	M4
57	35.8	25	29	21	23	16	18	16	12	11.4	35	27.2	19.2	4	5.7	3	5	M2.5×P0.45	M3×P0.5-5.5dp	M4×P0.7-4.5dp	M3×P0.5-6dp	M3×P0.5-5.5dp
70	43.2	31	36	24.5	30.6	24	22	23.2	15	16	47	36.9	24.9	5	7	4	8	M3×P0.5	M4×P0.7-8dp	M4×P0.7-4.5dp	M4×P0.7-8dp	M5×P0.8-8dp


Cylinder Internal dia.	ST Stroke (mm)	Weight (g) <sup>1</sup>	Included fitting	Applicable Sensor	Part Number		Unit price 1~10 pcs
					Type	No.	
10	8	60	Pipe fitting: 2 pcs (Applicable tube 6×4, 4×2.5)	CS-CHCSM5	<b>HC-CHHDLS</b>	10	<b>Quotation</b>
16	12	140				16	

<sup>1</sup>The weight is an approximate value. Consider it a guideline. Please check with our WOS for the purchase order that exceeds the displayed quantity.

**Order** **Part Number**  
 HC-CHHDLS10

**Days to Ship** **Quotation**

**Runner Chuck Mounting Example**

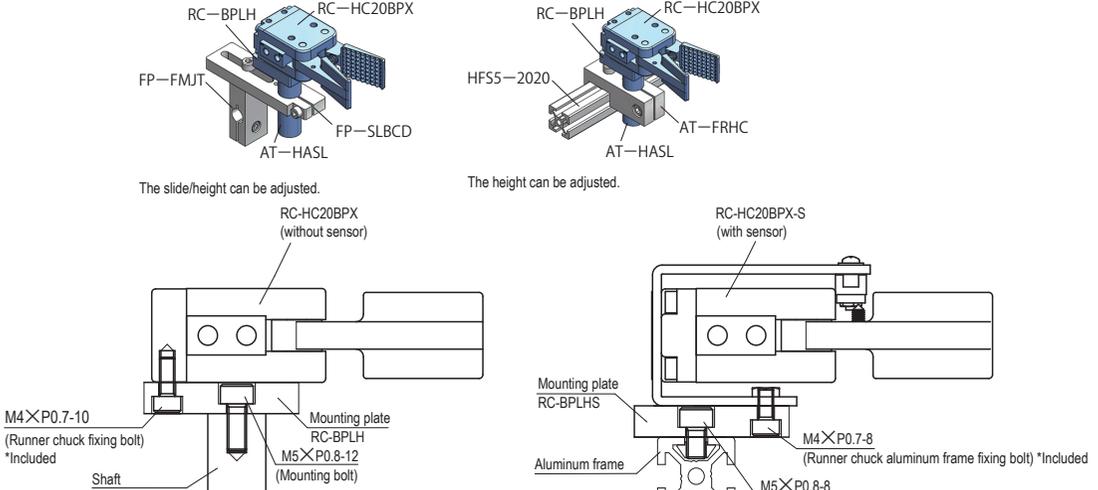

The slide/height can be adjusted.

The height can be adjusted.

Labels: RC-BPLH, RC-HC20BPX, FP-FMJT, AT-HASL, HF55-2020, AT-FRHC, RC-BPLHS, RC-HC20BPX-S, Mounting plate RC-BPLHS, Aluminum frame, M4×P0.7-10 (Runner chuck fixing bolt) \*Included, Shaft Pipe joint, M5×P0.8-12 (Mounting bolt), M4×P0.7-8 (Runner chuck aluminum frame fixing bolt) \*Included, M5×P0.8-8 (Mounting bolt).